

# Technical data sheet

## Height-adjustable cassette with cord outlet, RКСN, stainless steel

Item number: 7409208



Height-adjustable cassette of nominal size 4 with cord outlet for installation of accessories in dry-cleaned floors for indoor use.  
Height-adjustable cassette for cord outlet, 2-compartment. 2 APMT2 cover plates can be installed. For the installation of 2 UT3 universal supports for 4 individual installation devices with support ring/support clamp or 6 Modul 45 devices.



A2 Stainless steel

### Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 7409208                   |
| Type                               | RКСN2 4 VS 20             |
| Description 1                      | Square cassette           |
| Description 2                      | with cord outlet          |
| Manufacturer                       | OBO                       |
| Dimension                          | 200x200mm                 |
| Material                           | Stainless steel 1.4301    |
| Smallest sales unit                | 1                         |
| Unit of quantity                   | Piece                     |
| Weight                             | 305 kg                    |
| Weight unit                        | kg/100 pc.                |
| CO2 Footprint (GWP) Cradle-to-Gate | 14,9012 kg CO2e / 1 Piece |


# Technical data sheet

Height-adjustable cassette with cord outlet, RКСN, stainless steel

Item number: 7409208



## Dimensions

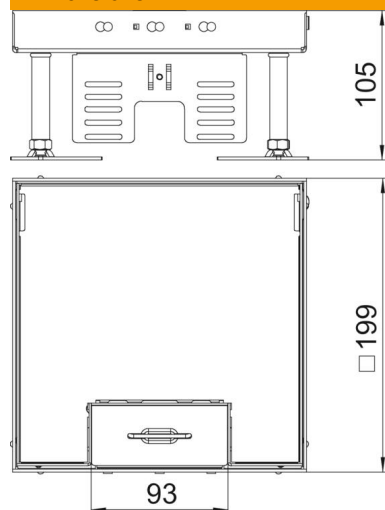

|             |        |
|-------------|--------|
| Length      | 199 mm |
| Width       | 199 mm |
| Dimension h | 105 mm |

## Technical data

|                                            |                         |
|--------------------------------------------|-------------------------|
| Number of installable devices              | 6                       |
| Number of mounting boxes                   | 2                       |
| Number of cable outlets                    | 1                       |
| Cover version                              | Square                  |
| Cable outlet version                       | Swivellable cord outlet |
| Floor care                                 | Dry                     |
| Decouplable                                | no                      |
| Floor height, max.                         | 150 mm                  |
| Floor height, min.                         | 105 mm                  |
| Suitable for raised floor installation     | yes                     |
| Suitable for cavity floor installation     | yes                     |
| Suitable for underfloor box                | 250/350                 |
| Device support to accept mounting boxes    | yes                     |
| Length of installation dimensions          | 201 mm                  |
| Nominal size for device installation units | 4                       |
| Height-adjustment range, max.              | 150 mm                  |
| Height-adjustment range, min.              | 105 mm                  |
| Protection rating (IP) when used           | IP20                    |
| Protection rating (IP) when unused         | IP40                    |
| Protection rating IK code                  | IK10                    |
| Heavy-duty version                         | no                      |
| Installation system type                   | UT3                     |
| Vertical load, large area                  | to 5,000 N              |
| Vertical load, small area                  | to 3,000 N              |
| Approvals                                  | VDE                     |
| Floor covering thickness                   | 20 mm                   |