

Technical data sheet

Collecting clamp Grip 10, plastic, OBO EcoLine

Item number: 2205382



Collection clamp with pointed fastening element, for the mounting of up to 10 cables NYM 3 x 1.5 m2 on walls or ceilings. Fastening with impact anchor or push-fit anchor. Also suitable for the fastening with gas- and battery-operated firing tools of the brands Bosch, Fischer and Spit (nose diameter Ø 7 mm). Fastening hole: Ø 6 mm. Recommended fastening distance of 250–400 cm when fully assigned, depending on the respective national specifications/norms.



PP
Eco Polypropylene Eco

Master data

Item number	2205382
Type	2031 10 ECO
Description 1	Grip collecting clamp
Description 2	with arrangement contour
Available from	08.03.2026
Manufacturer	OBO
Dimension	10x NYM3x1,5
Colour	Light grey; RAL 7035
Material	Polypropylene Eco
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.33 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0246 kg CO2e / 1 Piece


Technical data sheet

Collecting clamp Grip 10, plastic, OBO EcoLine

Item number: 2205382



Dimensions

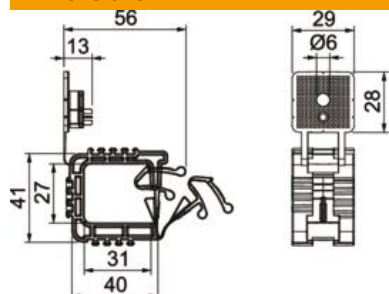

Technical data

No. of conductors NYM 3 x 1.5	10
Flame-resistant version	no
Breaking load	0.32 kN
Maintain electrical functions	no
Halogen-free	yes
With anchor	no
ROHS-conformant	yes