

Technical data sheet

Connection component with double crossbar

Item number: 5320709



- Quick mounting thanks to an M10 x 30 bolt made of stainless steel
- With spring washer
- 4 fastening holes Ø 5.2 mm, incl. rivets
- 2 fastening holes Ø 6.9 mm
- Corresponds to the requirements of VDE 0185-305 (IEC 62305)



A2 Stainless steel

Master data

Item number	5320709
Type	287 DCT A2
Description 1	Connection component
Description 2	with double crossbar
Manufacturer	OBO
Dimension	82x30x26
Material	Stainless steel
Smallest sales unit	10
Unit of quantity	Piece
Weight	9.32 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7897 kg CO2e / 1 Piece


Technical data sheet

Connection component with double crossbar

Item number: 5320709



Dimensions

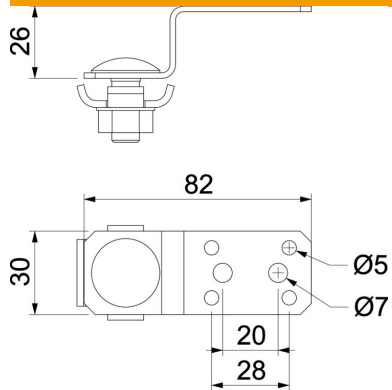

Technical data

Type of fastening screw	Gutter bolt
Type of connector	Connection terminal
Lightning current carrying capacity	H/100 kA
Suitable for round conductor diameters, max.	8 mm
Suitable for round conductor diameters, min.	6 mm
Fit	Rd 6 - 8 mm
ROHS-conformant	yes
Clamping range, max.	8 mm
Clamping range, min.	6 mm