

Technical data sheet

Set of Quick clips and Quick pipe pipes

Item number: 2154501



Set consisting of Quick pipe electrical installation pipes and Quick clip surface-mounted clips. For surface-mounted routing of cables in interiors and protected outdoor areas. Universal fastening on wall and ceiling. Comprises 50 m of pipe with each pipe 2 metres in length and 156 Quick clips. Can be used in a temperature range of -25 to + 60 °C.



PVC Polyvinylchloride

Master data

Item number	2154501
Type	2954 M16 LGR
Description 1	Quick-Pipe set
Description 2	Quick trunking + Quick clip
Manufacturer	OBO
Dimension	M16
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	444 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	9,7388 kg CO2e / 1 Piece


Technical data sheet

Set of Quick clips and Quick pipe pipes

Item number: 2154501



Dimensions

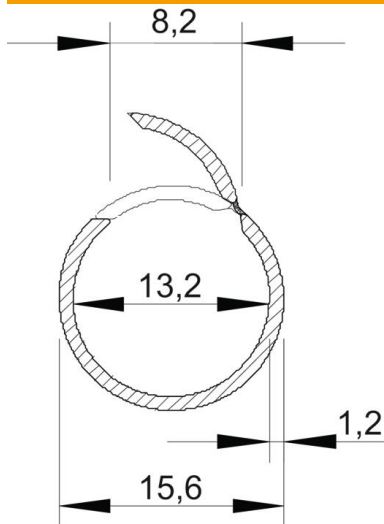

Dimension C	8,2 mm
Dimension D	15,6 mm
Dimension t	1,2 mm

Technical data

Surface-mounted	yes
Flame-resistant version	no
Concrete installation	yes
Size	M16
Halogen-free	no
Installation on wood	yes
Installation in the earth	no
Installation outdoors	no
Classification code	0
Machines and system installation	yes
With sleeve	no
ROHS-conformant	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C
Underfloor installation (screed)	no
Concealed	no