

Technical data sheet

SOM clip, single, hardly flammable

Item number: 2124459



With plastic screws, so corrosion-protected, with slot for fastening with wood screws or 5 mm knock-in anchors.

Hardly flammable.



Duroplast, Aminoplast

Master data

Item number	2124459
Type	3083 LGR
Description 1	SOM clip
Manufacturer	OBO
Dimension	32-45mm
Colour	Light grey; RAL 7035
Material	Duroplast, Aminoplast Typ 131.5
Smallest sales unit	20
Unit of quantity	Piece
Weight	5.84 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1608 kg CO2e / 1 Piece


Technical data sheet

SOM clip, single, hardly flammable

Item number: 2124459



Dimensions

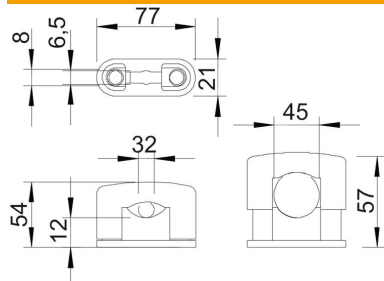

Dimension b	21 mm
Dimension b1	6.5 mm
Dimension d max.	45 mm
Dimension d min.	32 mm
Dimension H1	12 mm
Dimension H2	54 mm
Dimension H3	57 mm
Dimension L	77 mm

Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	yes
Halogen-free	yes
Plastic-covered	no
ROHS-conformant	yes
Bolt	M8 x 40
Clamping range D, max.	45 mm
Clamping range D, min.	32 mm
UV-resistant	no