

# Technical data sheet

## CL2512 profile rail, 11 mm slot, FS, unperforated

Item number: 1117033



Light-duty C profile rail for cable routing, in conjunction with series clips or clamp clips with N foot. Can also be used in building of control cabinets.



|    |                  |
|----|------------------|
| St | Steel            |
| FS | Strip galvanised |

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 1117033                 |
| Type                               | AL2512UP2000FS          |
| Description 1                      | Profile rail            |
| Description 2                      | unperforated, slot 11mm |
| Manufacturer                       | OBO                     |
| Dimension                          | 2000x25x12              |
| Material                           | Steel                   |
| Surface                            | Strip galvanised        |
| Surface standard                   | DIN EN 10346            |
| Smallest sales unit                | 2                       |
| Unit of quantity                   | Metre                   |
| Weight                             | 58.3 kg                 |
| Weight unit                        | kg/100 m                |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,304 kg CO2e / 1 Meter |


# Technical data sheet

CL2512 profile rail, 11 mm slot, FS, unperforated

Item number: 1117033



## Dimensions

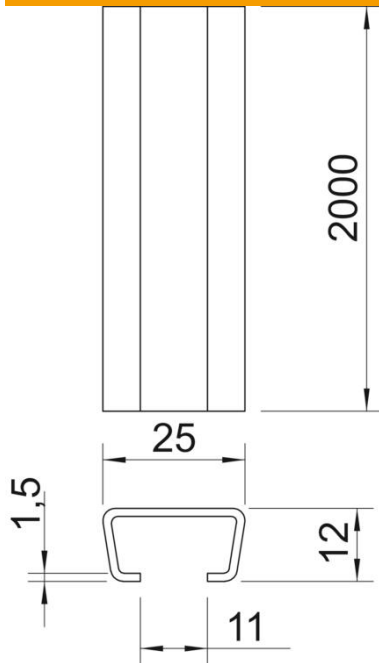

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Width       | 25 mm    |
| Height      | 12 mm    |
| Dimension L | 2,000 mm |

## Technical data

|                             |                      |
|-----------------------------|----------------------|
| Type of perforation         | Without              |
| Version for                 | Single profile       |
| Bundle                      | 20 m                 |
| Material thickness          | 1.5 mm               |
| With perforation            | no                   |
| With tothing                | no                   |
| Profile shape               | C profile            |
| Slot width                  | 11 mm                |
| Static value A              | 0.77 cm <sup>2</sup> |
| Static value I <sub>y</sub> | 0.14 cm <sup>4</sup> |
| Static value I <sub>z</sub> | 0.59 cm <sup>4</sup> |
| Static value W <sub>y</sub> | 0.19 cm <sup>3</sup> |
| Static value W <sub>z</sub> | 0.47 cm <sup>3</sup> |