

Technical data sheet

Beam clamp, horizontal A2

Item number: 6003960



Beam clamp for mounting light components on horizontal steel beams. Suitable, for example, for mesh cable trays and cable trays to 300 mm width or clips. The direction of the cable support system attached to the beam clamp is horizontal.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6003960
Type	BFK W 100 A2
Description 1	Clamping piece
Description 2	for horizontal application
Available from	01.03.2026
Manufacturer	OBO
Dimension	168x44x40
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	45.136 kg
Weight unit	kg/100 pc.


Technical data sheet

Beam clamp, horizontal A2


Item number: 6003960



Dimensions

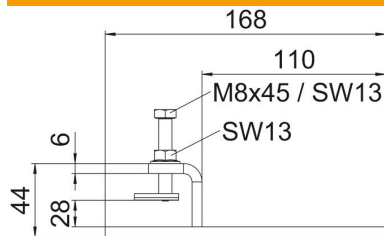

Length	168 mm
Width	110 mm
Height	32 mm

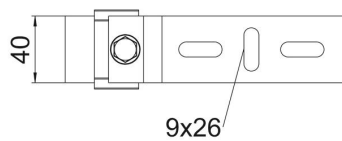

Technical data

Material thickness	6 mm
ROHS-conformant	yes
Rustproof steel, pickled	yes
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C