

Technical data sheet

Pluggable cover, unequipped

Item number: 2006040



Pluggable cover for the closing of junction boxes, equipped with 8 break-out openings for connection sockets by Wieland and Wago, 3- to 5-pole With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.

HALOGEN
FREE

650°

CE

IP
30

500
V

PP

Polypropylene

Master data	
Item number	2006040
Type	D01 L
Description 1	Plug-in cover
Description 2	for junction box, unequipped
Manufacturer	OBO
Dimension	150x116x39
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	8.042 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,308 kg CO2e / 1 Piece


Technical data sheet

Pluggable cover, unequipped

Item number: 2006040



Dimensions

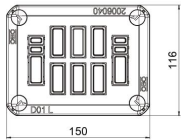

Length	150 mm
Width	116 mm
Height	39 mm

Technical data

Expandable	no
Version, concealed and cavity wall cover	Suitable for snap-in connector (manufacturer specific)
Fastening type	Screw fastening
Shape	Rectangular
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Halogen-free	yes
With connection cable	no
Protection rating	IP30