

Technical data sheet

Aluminium trunking cover

Item number: 6279720



Aluminium cover, for closing Rapid GA device installation trunking and ISS service poles with a 76.5 mm system opening. The firm position of the cover and electrical contact to the lower part of the trunking and service pole is guaranteed thanks to type RKV3V locking brackets. There are 6 pre-mounted locking brackets included per delivery length (2,000 mm).



Alu Aluminium

Master data

Item number	6279720
Type	GA-OTRW
Description 1	Cover
Manufacturer	OBO
Dimension	12x76,5x2000
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	2
Unit of quantity	Metre
Weight	38.3 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	4,9227 kg CO2e / 1 Meter


Technical data sheet

Aluminium trunking cover

Item number: 6279720



Dimensions

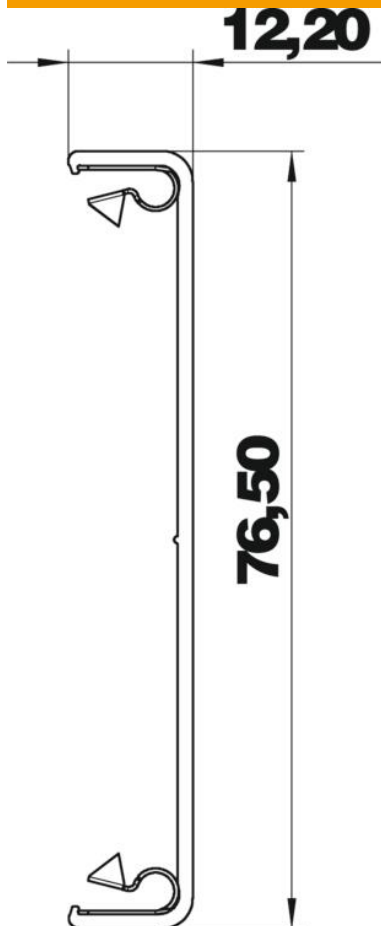

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C