


Technical data sheet

Mounting support for data technology connection sockets,
system length 208 mm
Item number: 7407840

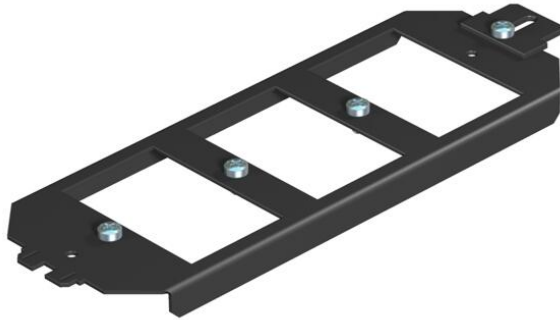

Mounting support for installation of three cover plates and strain relief. Use instead of a UT4 mounting box.




St Steel

FS Strip galvanised

Master data

Item number	7407840
Type	MTU 3
Description 1	Base support
Description 2	for support plate
Manufacturer	OBO
Dimension	208x76x12
Colour	Jet black; RAL 9005
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	14.47 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7004 kg CO2e / 1 Piece

Dimensions

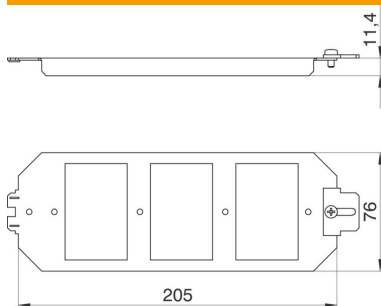

Length	205 mm
Width	76 mm

Technical data sheet

Mounting support for data technology connection sockets,
system length 208 mm

Item number: 7407840



Technical data

Connection options	3 support plates and strain relief
Number of installable devices	3
Number of strain reliefs	0
Version for	Support shape
Fastening type	Screw-on
Labelling panel	no
Floor covering protection frame	no
Floor plate	no
Lowerable to be flush-floor	no
Seal installation option	no
Installation opening for on-floor tank	no
Decouplable	no
Suitable for raised floor installation	yes
Suitable for screed-flush closed underfloor ducts	yes
Suitable for screed-covered underfloor ducts	yes
Suitable for cavity floor installation	yes
Suitable for underfloor ducts	yes
With floor covering recess	no
ROHS-conformant	yes
Heavy-duty version	no
Depth	11.4 mm
Strain relief option	yes