


# Technical data sheet

## Add-on tee, OBO EcoLine, FS

Item number: 6042179



Add-on tee made from CO2-reduced steel for the creation of a horizontal branch or cross-over. Fitting for latchable and screwable cable trays, side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used in indoor areas. Fastening material must be ordered separately.

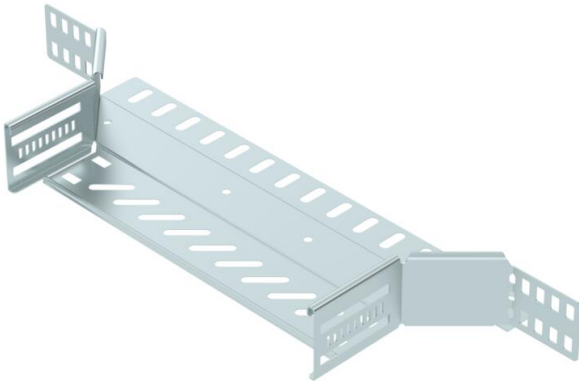

St

ECO

Steel, CO2 reduced

FS

Strip galvanised

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 6042179                  |
| Type                               | RAA 630 FS ECO           |
| Description 1                      | Add-on tee               |
| Description 2                      | for cable tray           |
| Available from                     | 06.03.2026               |
| Manufacturer                       | OBO                      |
| Dimension                          | 60x300                   |
| Colour                             | zinc                     |
| Material                           | Steel, CO2 reduced       |
| Surface                            | Strip galvanised         |
| Surface standard                   | DIN EN 10346             |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 49.9 kg                  |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,8619 kg CO2e / 1 Piece |


# Technical data sheet

Add-on tee, OBO EcoLine, FS

Item number: 6042179



## Dimensions

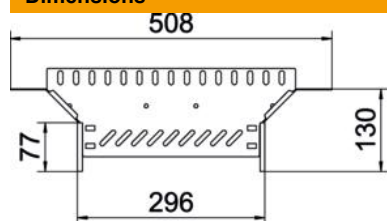

|                 |        |
|-----------------|--------|
| Width           | 300 mm |
| Height          | 60 mm  |
| Plate thickness | 0.8 mm |
| Dimension B     | 300 mm |

## Technical data

|                                         |                      |
|-----------------------------------------|----------------------|
| Departing width                         | 300 mm               |
| Connector version                       | Integrated connector |
| Maintain electrical functions           | yes                  |
| Material thickness, floor plate         | 0.8 mm               |
| NATO hole pattern                       | no                   |
| ROHS-conformant                         | yes                  |
| Rustproof steel, pickled                | no                   |
| Permitted temperature range, max.       | 120 °C               |
| Permitted temperature range, min.       | -20 °C               |
| Wide-span version                       | no                   |
| Type of connector, cable support system | screwed/clamped      |
| Recommended quantity of bolts           | 14 St.               |
| Rail thickness                          | 1.25 mm              |