


Technical data sheet

Lower part junction box, with fastening element

Item number: 2006010

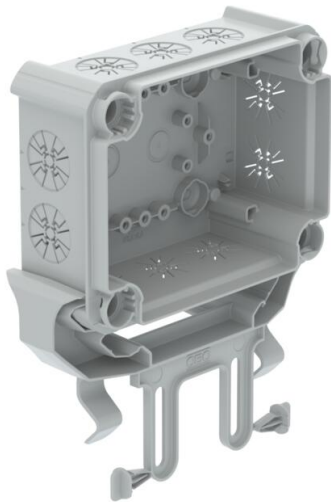

Pluggable lower part of junction box with universal fastening element for mounting on cable trays Unequipped, without cover. Halogen-free material and UV-resistant. Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



PP/GF Polypropylene, fibreglass reinforced

Master data

Item number	2006010
Type	UT01+SB BE
Description 1	Plug-in junction box
Description 2	with fixing element
Manufacturer	OBO
Dimension	201x165x67
Colour	Light grey; RAL 7035
Material	Polypropylene, fibreglass reinforced
Smallest sales unit	1
Unit of quantity	Piece
Weight	15.18 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,5595 kg CO2e / 1 Piece


Technical data sheet

Lower part junction box, with fastening element

Item number: 2006010



Dimensions

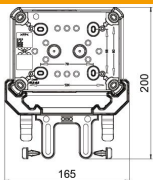

Length	201 mm
Width	165 mm
Height	67 mm

Technical data

No. of entries	10
Type of entry	Cable
Type of housing penetration	Pre-marking
Measured insulation voltage V_i	500 V
Equipment	Without
Cover	Without
Cover fastening	Not applicable
Entry from rear	yes
Entries	10
Explosion-tested version	no
Flame-resistant	acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C
Shape	Rectangular
Maintain electrical functions	Without
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Halogen-free	yes
With screening	yes
with lid	no
Mounting in the earth	no
Mounting underwater	no
Mounting type	Wall/ceiling mounting
Nominal cross-section, min.	10 mm ²
Nominal voltage	500 V
Sealable	no
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK07.
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Transparent lid	no
Weatherproof	no
Junction box cover version	Without