


Technical data sheet

Adjustable connector 160 A4

Item number: 6227967

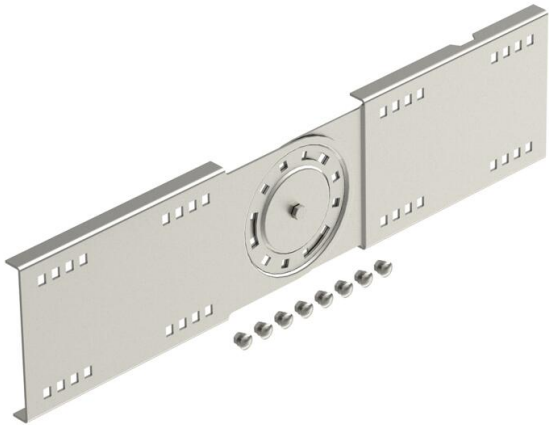

Adjustable connector for wide span cable trays and ladders with a side height of 160 mm.
Including appropriate bolts, washers and nuts.



A4	Stainless steel
2B	Bright, treated

Master data		
Item number	6227967	
Type	WRGV 160 A4	
Description 1	Adjustable connector	
Description 2	for wide span system 160	
Manufacturer	OBO	
Dimension	160x680	
Colour	stainless steel	
Material	Stainless steel 1.4571	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	2	
Unit of quantity	Piece	
Weight	300.3 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	18,465 kg CO2e / 1 Piece	


Technical data sheet

Adjustable connector 160 A4

Item number: 6227967



Dimensions

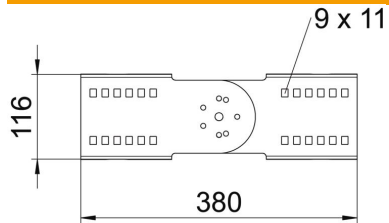

Length	680 mm
Width	20 mm
Height	160 mm
Plate thickness	2.5 mm

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Suitable for cable tray system height	160 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	yes
ROHS-conformant	yes
Rustproof steel, pickled	no
Connection type	Screw connector